

# Wall-mounted enclosures EL, 3-part



**System accessories** Page 507 **Socket strips** Page 422 **Wall mounting bracket** Page 587 **Cable clamps** Page 666

Wall-mounted enclosure with optimum accessibility due to hinged part.

**Material:**

- Wall and hinged part: Sheet steel, 1.5 mm
- Viewing window: Single-pane safety glass, 3 mm

**Surface finish:**

- Powder-coated

**Colour:**

- Wall and hinged part: RAL 7035
- Glazed door: RAL 7035/7015 (slate grey)

**Supply includes:**

- Wall section
  - Hinged part with 25 mm pitch pattern of holes in the front and rear frame
  - Designer glazed door
- Please note the product-specific scope of supply.

**Note:**


- Protection category IP 54 in conjunction with solid gland plate, top and bottom
- Enclosure 673 mm deep with reinforced wall mounting bracket

**Approvals:**

- UL
- cUL

**Technical details:**

Available on the Internet

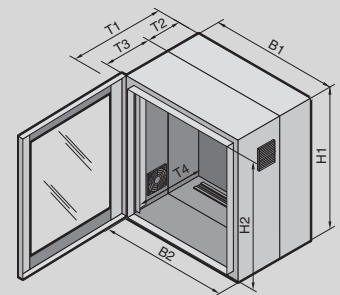

## pre-configured with mounting angles, depth-variable

Units U	Packs of	9	9	15	15	21	21	Page
<b>Width (B1) mm</b>		600	600	600	600	600	600	
<b>Height (H1) mm</b>		478	478	746	746	1012	1012	
<b>Depth (T1) mm</b>		573	673	573	673	573	673	
Clearance width (B2) mm		502	502	502	502	502	502	
Clearance height (H2) mm		415	415	683	683	949	949	
Depth of wall section (T2) mm		135	135	135	135	135	135	
Depth of hinged part (T3) mm		416	516	416	516	416	516	
Max. installation depth (T4) mm		520	620	520	620	520	620	
Load capacity of hinged part (static) kg		45	45	75	75	75	75	
<b>Model No.</b>	1 pc(s).	<b>7709.735</b>	<b>7709.535</b>	<b>7715.735</b>	<b>7715.535</b>	<b>7721.735</b>	<b>7721.535</b>	
<b>Product-specific scope of supply</b>								
Wall section: Gland plate, solid, top		■	■	■	■	■	■	
Wall section: Gland plate with brush strip, bottom		■	■	■	■	■	■	
Wall section: 2 vertical punched rails		■	■	■	■	■	■	
Wall section: C rail mounted horizontally for cable clamping		■	■	■	■	■	■	
Hinged part with two 482.6 mm (19") mounting angles, fully depth adjustable		■	■	■	■	■	■	
Hinged part: Side outlet filters left and right		■	■	■	■	■	■	
Earth rail with star earthing		■	■	■	■	■	■	
4 wall mounting brackets 10 mm		■	■	■	■	■	■	
Mini-comfort handle		■	■	■	■	-	-	
Security lock 3524 E		■	■	■	■	■	■	
Comfort handle and 2-point locking		-	-	-	-	■	■	
<b>Accessories</b>								
Gland plate for metric cable glands	1 pc(s).	7705.235	7705.235	7705.235	7705.235	7705.235	7705.235	656
Fan expansion kit	1 set(s)	7980.100	7980.100	7980.100	7980.100	7980.100	7980.100	438
Spare filter mats	5 pc(s).	3322.700	3322.700	3322.700	3322.700	3322.700	3322.700	371
Wall mounting bracket		see page	-	see page	-	see page	-	587
Component shelf 2 U, static installation	1 pc(s).	7119.250	see page	7119.250	see page	7119.250	see page	631
Cable management panel	1 pc(s).	7257.200	7257.200	7257.200	7257.200	7257.200	7257.200	674