

Wall-mounted enclosures EL, 3-part



System accessories Page 507 **Socket strips** Page 422 **Wall mounting bracket** Page 587 **Earthing** Page 644

Wall-mounted enclosure with optimum accessibility due to hinged part.

Material:

- Wall and hinged part: Sheet steel, 1.5 mm
- Viewing window: Single-pane safety glass, 3 mm

Surface finish:

- Powder-coated

Colour:

- Wall and hinged part: RAL 7035
- Glazed door: RAL 7035/7015 (slate grey)

Protection category IP to IEC 60 529:

- IP 55

Supply includes:


- Wall section
 - Hinged part with 25 mm pitch pattern of holes in the front and rear frame
 - Designer glazed door
- Please note the product-specific scope of supply.

Approvals:

- UL
- cUL

Technical details:

Available on the Internet

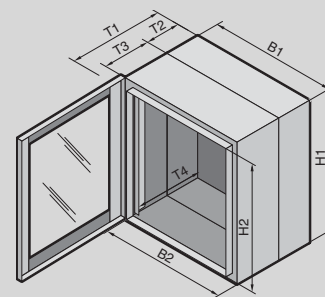

with punched rails and mounting angles, depth-variable

Units U	Packs of	6	9	12	15	21	Page
Width (B1) mm		600	600	600	600	600	
Height (H1) mm		345	478	612	746	1012	
Depth (T1) mm		473	473	473	473	473	
Clearance width (B2) mm		502	502	502	502	502	
Clearance height (H2) mm		282	415	549	683	949	
Depth of wall section (T2) mm		135	135	135	135	135	
Depth of hinged part (T3) mm		316	316	316	316	316	
Max. installation depth (T4) mm		420	420	420	420	420	
Load capacity of hinged part (static) kg		30	45	60	75	75	
Model No.	1 pc(s).	7706.135	7709.135	7712.135	7715.135	7721.135	
Product-specific scope of supply							
Wall section: Gland plate, solid, top and bottom		■	■	■	■	■	
Wall section: 2 vertical punched rails		■	■	■	■	■	
Wall section: C rail mounted horizontally for cable clamping		■	■	■	■	■	
Hinged part with two 482.6 mm (19") mounting angles, fully depth adjustable		■	■	■	■	■	
4 wall mounting brackets 10 mm		■	■	■	■	■	
Mini-comfort handle		■	■	■	■	-	
Security lock 3524 E		■	■	■	■	■	
Comfort handle and 2-point locking		-	-	-	-	■	
Accessories							
Gland plate with brush insert	1 pc(s).	7705.035	7705.035	7705.035	7705.035	7705.035	657
Gland plate for metric cable glands	1 pc(s).	7705.235	7705.235	7705.235	7705.235	7705.235	656
Wall mounting bracket		see page	see page	see page	see page	see page	587
Earth rail, horizontal	1 pc(s).	7113.000	7113.000	7113.000	7113.000	7113.000	646
Component shelf 2 U, static installation	1 pc(s).	7119.250	7119.250	7119.250	7119.250	7119.250	631
Cable management panel	1 pc(s).	7257.200	7257.200	7257.200	7257.200	7257.200	674
Lock systems		from page	from page	from page	from page	from page	560