

Interior installation

Component shelves for attachment to the 19" system punchings

Component shelf 2 U, static installation

482.6 mm (19")

for 482.6 mm (19") system punchings

For mounting between 482.6 mm (19") mounting angles.

Load capacity:

- 25 kg surface load, static

Material:

- Sheet steel

Surface finish:

- Spray-finished

Supply includes:

- Assembly parts

Component shelf depth mm	Colour RAL	Packs of	Model No.
250	7035	1 pc(s).	7119.250
	9005	1 pc(s).	5501.615
400	7035	1 pc(s).	7119.400
	9005	1 pc(s).	5501.625


Note:

- Not suitable for combination with telescopic slides



Also required:

- Captive nuts, see page 624
- Screws, see page 625

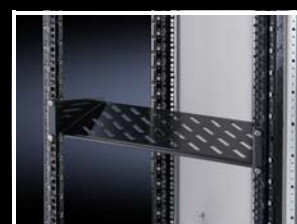

Installation kit, depth-variable

for 482.6 mm (19") component shelves

Depending on the distance between the two 482.6 mm (19") levels, the installation kit is screw-fastened directly to the 482.6 mm (19") system punchings in the depth.

Material:

- Sheet steel

Surface finish:

- Zinc-plated

Supply includes:

- Assembly parts

482.6 mm (19") distance between levels mm	Packs of	Model No.
550 - 850	2 pc(s).	7063.850