

# FlatBox



## System accessories Page 507

For flexible use as a wall-mounted or floor-standing enclosure.

### Benefits:

- Tool-free quick assembly
- System assembly on the open 482.6 mm (19") frame

### Material:

- Sheet steel
- Viewing window: Single-pane safety glass, 3 mm

### Surface finish:

- Powder-coated

### Colour:

- RAL 7035

### Supply includes:

- Flat-packed enclosure
- 1 wall section
- 2 basic supports
- 2 roof/base plates, with cut-outs for cable entry via brush strips
- 2 side panels, lockable
- 1 glazed door, lockable, security lock 3524 E, door hinge point selectable
- Connection components for tool-free, fast assembly
- Earthing kit for system-compatible earthing of all enclosure parts

Please note the product-specific scope of supply.

### Note:

- Max. installation depth: Depth – 112 mm
- Max. distance between two 482.6 mm (19") levels: Depth – 126 mm

### Technical details:

Available on the Internet

Photo shows a configuration example with equipment not included in the scope of supply


## Design with 482.6 mm (19") mounting angles

Units U	Packs of	6	6	9	9	Page
Width mm		600	600	600	600	
Height mm		358	358	492	492	
Depth mm		400	600	400	600	
Model No.	1 pc(s).	<b>7507.000</b>	<b>7507.100</b>	<b>7507.010</b>	<b>7507.110</b>	
<b>Product-specific scope of supply</b>						
482.6 mm (19") mounting angles	2 pc(s).	■	■	■	■	
<b>Accessories</b>						
Mounting angles, 482.6 mm (19")	2 pc(s).	7507.706	7507.706	7507.709	7507.709	686
Levelling feet	4 pc(s).	7507.740	7507.740	7507.740	7507.740	520
Cover plates for fan panels	6 pc(s).	7507.760	7507.760	7507.760	7507.760	440
Earth rail, horizontal	1 pc(s).	7113.000	7113.000	7113.000	7113.000	646
Cable clamp, variable		see page	see page	see page	see page	669
Fan expansion kit		see page	see page	see page	see page	438
Enclosure internal thermostat	1 pc(s).	3110.000	3110.000	3110.000	3110.000	379
Cable management panel	1 pc(s).	5502.205	5502.205	5502.205	5502.205	674
Component shelf 2 U, static installation	1 pc(s).	7119.250	see page	7119.250	see page	631
Component shelves, pull-out	1 set(s)	–	5501.675	–	5501.675	630

## Design with 482.6 mm (19") mounting frame

Units U	Packs of	12	12	15	15	18	21	Page
Width mm		600	600	600	700	700	700	
Height mm		625	625	758	758	892	1025	
Depth mm		400	600	400	700	700	700	
<b>Model No.</b>	1 pc(s).	<b>7507.020</b>	<b>7507.120</b>	<b>7507.030</b>	<b>7507.200</b>	<b>7507.210</b>	<b>7507.220</b>	
<b>Product-specific scope of supply</b>								
482.6 mm (19") mounting frame	1 pc(s).	■	■	■	■	■	■	
Levelling feet	4 pc(s).	■	■	■	■	■	■	
<b>Accessories</b>								
Mounting angles, 482.6 mm (19")	2 pc(s).	7507.712	7507.712	7507.715	7507.715	7507.718	7507.721	686
Levelling feet	4 pc(s).	7507.740	7507.740	7507.740	7507.740	7507.740	7507.740	520
Cover plates for fan panels	6 pc(s).	7507.760	7507.760	7507.760	7507.760	7507.760	7507.760	440
Earth rail, horizontal	1 pc(s).	7113.000	7113.000	7113.000	7113.000	7113.000	7113.000	646
Cable clamp, variable		see page	see page	see page	see page	see page	see page	669
Fan expansion kit		see page	see page	see page	see page	see page	see page	438
Enclosure internal thermostat	1 pc(s).	3110.000	3110.000	3110.000	3110.000	3110.000	3110.000	379
Cable management panel	1 pc(s).	5502.205	5502.205	5502.205	5502.205	5502.205	5502.205	674
Component shelf 2 U, static installation	1 pc(s).	7119.250	see page	7119.250	see page	see page	see page	631
Component shelves, pull-out	1 set(s)	–	5501.675	–	5501.675	5501.675	5501.675	630

## Accessories

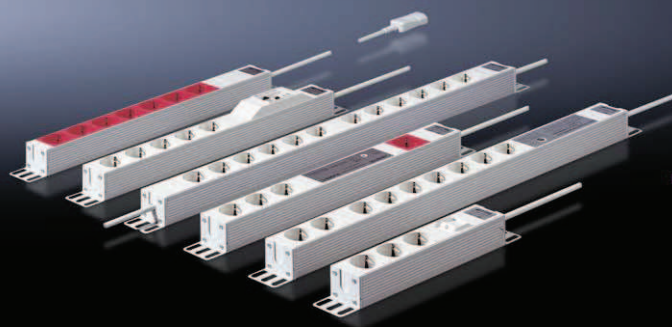

## Socket strips

see from page 422