

System accessories AX

Roof



Rain canopy

for AX

Installation options:

- Secured with adhesive; no need for machining
- May also be screw-fastened for dynamic loads

Material:

- Stainless steel 1.4301 (AISI 304)

Surface finish:


- Brushed, grain size 240

Supply includes:

- Assembly parts


For		H	Model No.
Enclosure width mm	Enclosure depth T mm		
300	210	37	2361.010
380	210	37	2472.010
500	210	37	2362.010
600	210	37	2473.010
600	350	47	2476.010
760	300	43	2474.010
800	300	43	2475.010
1000	300	43	2363.010

Side view

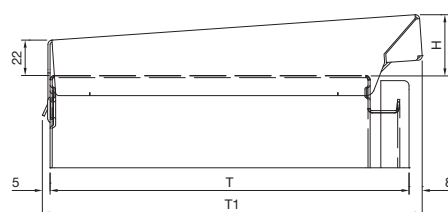

$T1 = \text{Enclosure depth } T + 13 \text{ mm}$

Rear view

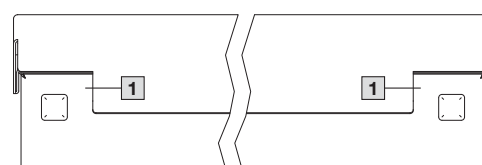

1 Recess for wall mounting bracket



Dust guard trim

for AX, KX

To protect against deposits on the upper edge of the door and between the enclosure and the door/cover. Cut the dust guard trim to length according to the enclosure width. Drill the enclosure and fit the dust guard trim using the adhesive strips and screws.

Material:

- Plastic, UV-resistant

Colour:

- Similar to RAL 7024

Length mm	Model No.
1200	2426.500



Eyebolts

for AX

For crane transportation of enclosures, with reinforcement plate to be inserted underneath.

Thread: M12

Supply includes:

- Eyebolts
- Reinforcement plates

Packs of	Model No.
2 pc(s).	2509.010