

# Command panel housings with door



System accessories Page 507 Support arm system CP 40 stainless steel Page 140 Hygienic Design Page 169

## Material:

- Enclosure and door: Stainless steel 1.4301 (AISI 304)
- Handle strips: Plastic approved for use with foodstuffs

## Surface finish:

- Brushed, grain 240

## Colour:

- Handle strips: similar to RAL 5002

## Protection category IP to IEC 60 529:


- IP 66

## Supply includes:

- Enclosure of all-round solid construction
- Cut-out and reinforcement for support arm system CP 40 stainless steel
- Fastener with guide plate
- Door with sealing frame and side handle strips
- Lock: 3 mm double-bit

## Note:

- The support arm connection and door hinge may be swapped over by rotating the enclosure
- Matching mounting plates from compact enclosures AE may be used
- 3 mm double-bit lock insert may be exchanged for 41 mm lock inserts, plastic handles and T handles, type C

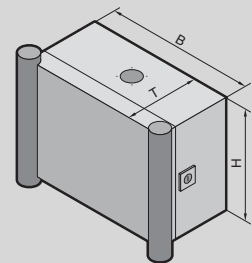

## Approvals:

- UL
- cUL
- TÜV

## Technical details:

Available on the Internet

## Stainless steel

Width (B) mm	Packs of	300	400	400	600	Page
Height (H) mm		300	300	400	400	
Depth (T) mm		150	150	150	150	
Model No.	1 pc(s).	<b>6535.010</b>	<b>6536.010</b>	<b>6538.010</b>	<b>6539.010</b>	
Weight kg		6.3	7.5	8.8	12.1	
<b>Accessories</b>						
Support rails TS 35/7.5	10 pc(s).	2316.000	2317.000	2317.000	-	614
Lock systems		from page	from page	from page	from page	563