



## System accessories Page 507

### Applications:

- Zone 1 and 2 or 21 and 22 to 94/9/EC
- Ambient temperature range: -30°C...+80°C
- Protection type to EN 60 079: Equipment protection due to increased safety, equipment protection due to enclosure

### Material:

- Enclosure: Stainless steel 1.4301 (AISI 304)
- Door: Stainless steel 1.4301 (AISI 304), all-round foamed-in silicone seal
- Mounting plate: Sheet steel

### Surface finish:

- Enclosure: Brushed, grain 240
- Mounting plate: Zinc-plated

### Protection category IP to IEC 60 529:

- IP 66

### Supply includes:

- Enclosure
- Door
- Mounting plate

### Certificates:


- PTB 02 ATEX 1082U
- IEC Ex PTB 09.0035U

### Approvals:

- ATEX
- IEC

### Technical details:

Available on the Internet

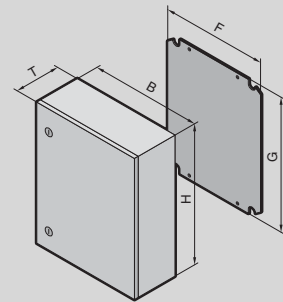

## Stainless steel, empty enclosure with hinged door

Width (B) mm	Packs of	200	300	380	380	380	600	600	760	800	Page
Height (H) mm		300	380	300	380	600	600	760	760	1000	
Depth (T) mm		155	210	155	210	210	210	210	300	300	
Mounting plate width (F) mm		162	334	334	334	334	549	549	704	739	
Mounting plate height (G) mm		275	275	275	355	570	570	730	730	955	
<b>Model No.</b>	1 pc(s).	<b>9401.600</b>	<b>9409.600</b>	<b>9402.600</b>	<b>9403.600</b>	<b>9404.600</b>	<b>9405.600</b>	<b>9406.600</b>	<b>9407.600</b>	<b>9408.600</b>	
Cam lock with 3 mm double-bit insert		1	1	1	1	2	2	2	2	2	
Reinforcement section in the door		-	-	-	-	-	■	■	■	■	
Weight kg		3.8	7.7	7.4	9.7	13.3	15.6	22.3	30.5	36.3	

### Accessories

Wall mounting bracket	4 pc(s).	2433.000	2433.000	2433.000	2433.000	2433.000	2433.000	2433.000	2433.000	2433.000	587
Support rails TS 35/7.5	10 pc(s).	2315.000	2316.000	-	-	-	-	-	-	-	614
Rails for interior installation	4 pc(s).	-	2383.210	-	2383.210	2383.210	2383.210	2383.210	2383.300	2383.300	605
Support rails TS 35/15	10 pc(s).	-	-	-	-	-	2319.000	2319.000	-	-	614
Earth straps		see page	see page	see page	see page	see page	see page	see page	see page	see page	644