



For enclosure depth 800 mm

A Gland plate set	Packs of	Packs required	For enclosure width mm	
			600	800
Model No.				
Gland plate, solid, with sliding panel, multi-piece	1 set(s)	1	–	5502.530


Gland plate modules	Packs of	Packs required	For enclosure width mm	
			600	800

B 1 module plate as selected				Model No.	
Gland plate, depth 250 mm	1 pc(s).	1	5001.222	5001.223	
Gland plate, depth 100 mm	1 pc(s).	1	5001.214	5001.215	
Sliding panel, depth 150 mm	1 pc(s).	1	5001.239	5001.240	
Module plate, depth 237.5 mm	1 pc(s).	1	Cable entry with brush strip	7825.361	7825.381
			Vented	7825.360	7825.380
			Cable entry with brush strip, super-airtight	7825.367	7825.387
			Cable entry, side	–	7825.388

C 2 module plates as selected				Model No.	
Gland plate, depth 150 mm	1 pc(s).	1	5001.218	5001.219	
Sliding panel, depth 150 mm	1 pc(s).	1	5001.239	5001.240	
Module plate, depth 237.5 mm	1 pc(s).	2	Cable entry with brush strip	7825.361	7825.381
			Vented	7825.360	7825.380
			Cable entry with brush strip, super-airtight	7825.367	7825.387
			Cable entry, side	–	7825.388

D Cable entry, rear or front				Model No.	
Gland plate, depth 250 mm	1 pc(s).	1	5001.222	5001.223	
Gland plate, depth 150 mm	1 pc(s).	1	5001.218	5001.219	
Sliding panel, depth 150 mm	1 pc(s).	2	5001.239	5001.240	
Foam rubber cable clamp strip	3 m	1	2573.000	2573.000	

E Cable entry, centre				Model No.	
Gland plate, depth 250 mm	1 pc(s).	1	5001.222	5001.223	
Gland plate, depth 150 mm	1 pc(s).	1	5001.218	5001.219	
Sliding panel, depth 150 mm	1 pc(s).	2	5001.239	5001.240	
Section for cable entry, centre	1 set(s)	1	8802.060	8802.080	

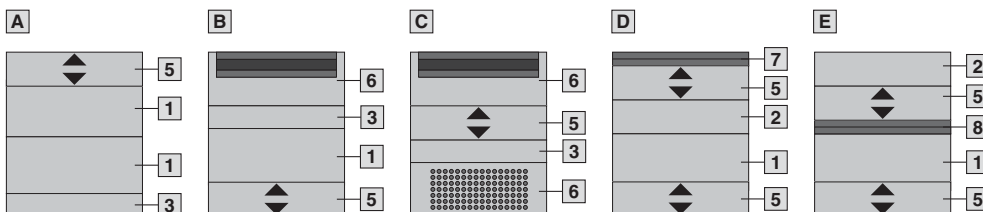

- 1 Gland plate, depth 250 mm
- 2 Gland plate, depth 150 mm
- 3 Gland plate, depth 100 mm
- 4 Gland plate, depth 50 mm
- 5 Sliding panel, depth 150 mm
- 6 Module plate, depth 237.5 mm
- 7 Self-adhesive foam cable clamp strip
- 8 Section for cable entry, centre

! Also required:

– Base mount, see page 524