

# Cable management

## Gland plates

### Plastic cable gland plates

#### with metric knockouts

With pre-punched holes for cable glands. Used for sealing standard gland plates.

#### Temperature range:

– Suitable for use from -40°C...+70°C

#### Colour:

– RAL 7035

#### Protection category IP to IEC 60 529:

– IP 55 if installed correctly


#### Note:

– The applicable size may be taken from the respective product ordering page



Size	Packs of	Model No.
1	10 pc(s).	<b>2560.010</b>
3	10 pc(s).	<b>2561.010</b>
4	5 pc(s).	<b>2562.010</b>
5	5 pc(s).	<b>2563.010</b>




Size 1

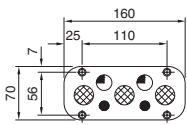


Size 3

 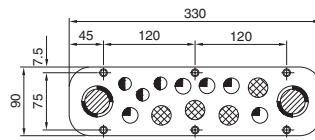

Size 4

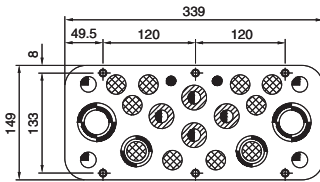

Size 5

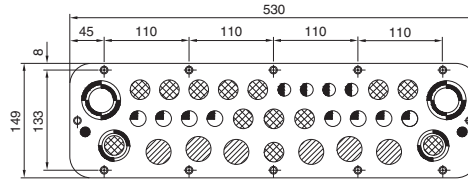

### Plastic cable gland plates

#### with PG knockouts

With pre-punched PG holes for cable glands. Used for sealing standard gland plates.

#### Temperature range:

– Suitable for use from -40°C...+70°C

#### Material:

– ABS

#### Colour:

– RAL 7035

#### Protection category IP to IEC 60 529:


– IP 55 if installed correctly

#### Note:

– The applicable size may be taken from the respective product ordering page

Size	PG	Qty.	Packs of	Model No.
2	13.5	12	5 pc(s).	<b>1581.000</b>
	13.5	6	5 pc(s).	<b>1582.000</b>
	16	2		
	21	2		

1581.000

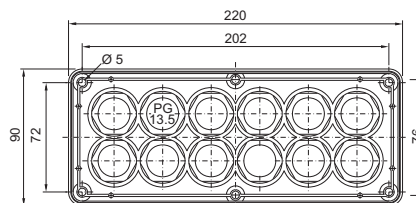

1582.000

