

Cable management

Gland plates

Metal gland plates

with metric knockouts

Simply knock out the holes for the cable glands using a screwdriver.

Material:

– Sheet steel

Colour:

– RAL 7035


Protection category IP to IEC 60 529:

– IP 66 when mounting in the usual position at the bottom


Note:

– The applicable size may be taken from the respective product ordering page


Size 2

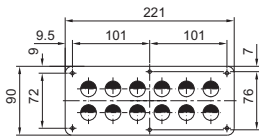

Size 3

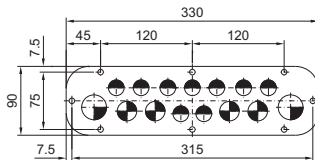

Size 4

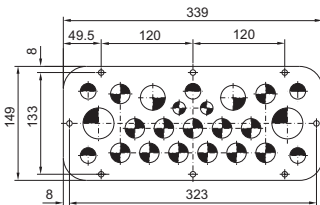

Size	Packs of	Model No.
2	1 pc(s).	1581.100
3	1 pc(s).	2561.100
4	1 pc(s).	2562.100
5	1 pc(s).	2563.100

Number of cable entries

Diameter						Model No.
M12	M16	M20	M25	M32	M40	
–	–	12	–	–	–	1581.100
–	–	9	4	2	–	2561.100
–	2	5	13	2	2	2562.100
1	–	12	11	8	4	2563.100



Accessories:

– Cable glands made from polyamide or brass, see page 658

