

# 482.6 mm (19") installation system

## 482.6 mm (19") installation

### Drawer, 2 U, 3 U

#### for a 482.6 mm (19") attachment level

For front attachment to mounting angles, 482.6 mm (19"). With cover and telescopic slides to accommodate assignment lists, operating manuals and small parts. The small version of the 2 U variant is also suitable for mounting inside a swing frame.


#### Material:

- Sheet steel

#### Supply includes:

- Fully assembled, including assembly parts

Height	Clearance openings		Installation depth mm	Colour		Packs of	Model No.
	Width mm	Depth mm		RAL 7035	RAL 9005		
2 U	411	419	427	■	-	1 pc(s).	<b>7282.035</b>
2 U	411	419	427	-	■	1 pc(s).	<b>5502.305</b>
3 U	411	419	427	■	-	1 pc(s).	<b>7283.035</b>
3 U	411	419	427	-	■	1 pc(s).	<b>5502.325</b>

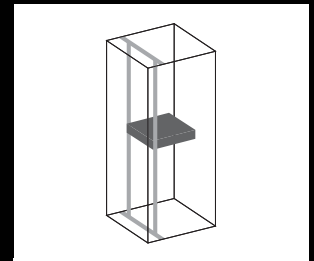

### Installation kit

#### for component shelves with 482.6 mm (19") adaptor sections in TS

For installation between the front and rear adaptor sections or adaptor pieces, 482.6 mm (19") in 600 mm wide enclosures.

#### Material:

- Sheet steel

#### Surface finish:

- Zinc-plated

#### Supply includes:

- Assembly parts

#### For enclosure system TS

For enclosure depth mm	Packs of	Model No.
600	1 set(s)	<b>8800.560</b>
800	1 set(s)	<b>8800.580</b>

Max. depth of component shelves =  
Enclosure depth - 100 mm



#### Also required:

- Adaptor sections, 482.6 mm (19"), see page 683, or
- Adaptor pieces, 482.6 mm (19"), see page 684

