

Doors/locks

Viewing panels/operating panels



Viewing window

Stainless steel

Fitted as standard with internal 130° hinges and all-round seal. The double-bit lock insert may be exchanged for 27 mm lock inserts, type A, and Ergoform-S handle 2452.000.

Material:

- Stainless steel 1.4301 (AISI 304)
- Single-pane safety glass

Protection category IP to IEC 60 529:

- IP 54

Supply includes:

- Assembly parts




Width mm	Height mm	Depth mm	Model No.
522	600	38	2793.560



Accessories:

- Lock inserts, 27 mm, type A, see page 680
- Ergoform-S handle 2452.000, see page 678

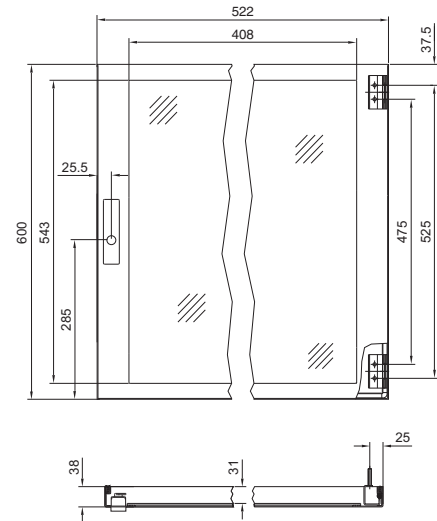

Monitor frame

for door width 600 and 800 mm

For covering a door cut-out, for all standard monitors up to 482.6 mm (19").

Protection category IP to IEC 60 529:

- IP 54

Supply includes:

- Safety glass panel

Dimensions	Width mm	Height mm	Model No.
External dimensions	470	430	2305.000
Viewing area	375	325	
Cut-out required	415	375	



Identification strips

For individual field identifiers on the door, including transparent cover and assembly parts.

For labels:

Width: Enclosure width - 150 mm
Height: 29 mm
Thickness: 0.75 mm

Colour:

- RAL 7033

For enclosure width mm	Model No.
600	2403.000
800	2404.000