

# Interior installation

## Mounting plates

### Partial mounting plates

for TS, SE

For

- Universal interior installation, also in conjunction with punched sections with mounting flanges and support strips; defective assemblies are easily and quickly replaced
- Additional mounting levels

Partial mounting plates are fastened directly onto the vertical enclosure sections via the inner mounting level using the assembly parts supplied loose. In this mounting position (in both the width and the depth) they form one level with TS punched sections with mounting flanges 17 x 73 mm and TS support strips for the inner mounting level.

#### Material:

- Sheet steel, 2.5 mm

#### Surface finish:

- Zinc-plated

#### Supply includes:

- Assembly parts




#### Accessories:

- TS punched section with mounting flange 17 x 73 mm for the outer mounting level, see page 717
- TS support strip, see page 720
- Hinge attachment, see page 708
- Self-tapping screws, 2487.000, see page 737



For installation in										Size mm	Packs of	Model No.
Enclosure width mm					Enclosure depth (side) mm							
400	600	800	1000	1200	400	500	600	800				
■	■				■		■			500 x 300	1 pc(s).	<b>8614.640</b>
	■					■	■			500 x 400	1 pc(s).	<b>8614.650</b>
	■						■			500 x 500	1 pc(s).	<b>8614.660</b>
	■	■					■	■		500 x 700	1 pc(s).	<b>8614.680</b>
	■						■			500 x 775	1 pc(s).	<b>8614.675<sup>1)</sup></b>
■		■			■			■		700 x 300	1 pc(s).	<b>8614.840</b>
		■					■	■		700 x 400	1 pc(s).	<b>8614.850</b>
		■						■		700 x 700	1 pc(s).	<b>8614.880</b>
■			■		■					900 x 300	1 pc(s).	<b>8614.040</b>
			■			■				900 x 400	1 pc(s).	<b>8614.050</b>
	■		■				■			900 x 500	1 pc(s).	<b>8614.060</b>
■				■	■					1100 x 300	1 pc(s).	<b>8614.240</b>
				■		■				1100 x 400	1 pc(s).	<b>8614.250</b>
	■			■			■			1100 x 500	1 pc(s).	<b>8614.260</b>

<sup>1)</sup> Also suitable for installing in  
 - PC enclosures based on SE behind the lower front door  
 - IW enclosures, height 900 and 1000 mm


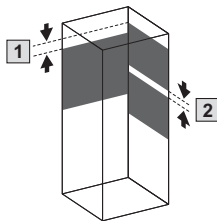


When **installing around corners** due to collision between the assembly components

- 1** At least 75 mm (adjustable on a 25 mm pitch pattern)


Maximum space utilisation

  - 2** 1 mm (adjustable on a 25 mm pitch pattern)



#### Set forward installation position

Quickly and easily achieved with four TS punched sections with mounting flanges 17 x 73 mm for the outer mounting level, see page 717

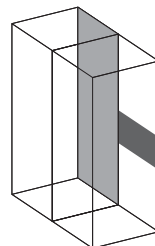

#### Continuously flush

In bayed enclosure suites, the partial mounting plate is in the rearmost position flush with the standard mounting plate; this facilitates continuous component mounting