


# Compartment configuration

## Form 1-4

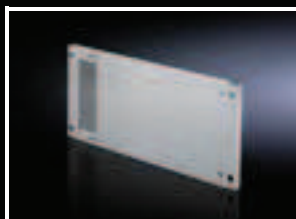

### Partial mounting plates

#### With or without duct

- For direct attachment to the functional space side panel modules.
- Universal internal installation with switchgear and control devices.
- Additional mounting levels.
- In combination with functional space dividers and side panel modules, internal separation in accordance with Form 2, 3 or 4 is possible.

#### Material:

Sheet steel, zinc-plated, passivated, 2 mm

#### Supply includes:

- Angle brackets and assembly parts
- For the version with duct:  
Additional square cut-out with insulating plates for sealing the cut-out.



#### Also required:

Functional space side panel modules, see page 345.

#### With duct

For enclosure width mm	For compartment height mm	Width mm	Height mm	Packs of	Model No. SV
600	150	502	143	1	<b>9673.671</b>
600	200	502	193	1	<b>9673.672</b>
600	250	502	243	1	<b>9673.677</b>
600	300	502	293	1	<b>9673.673</b>
600	400	502	393	1	<b>9673.674</b>
800	150	702	143	1	<b>9673.691</b>
800	200	702	193	1	<b>9673.692</b>
800	250	702	243	1	<b>9673.697</b>
800	300	702	293	1	<b>9673.693</b>
800	400	702	393	1	<b>9673.694</b>

#### Without duct

For enclosure width mm	For compartment height mm	Width mm	Height mm	Packs of	Model No. SV
400	150	302	143	1	<b>9673.641</b>
400	200	302	193	1	<b>9673.642</b>
400	250	302	243	1	<b>9673.647</b>
400	300	302	293	1	<b>9673.643</b>
400	400	302	393	1	<b>9673.644</b>
400	600	302	593	1	<b>9673.646</b>
400	800	302	793	1	<b>9673.648</b>
400	1000	302	993	1	<b>9673.640</b>
600	150	502	143	1	<b>9673.661</b>
600	200	502	193	1	<b>9673.662</b>
600	250	502	243	1	<b>9673.667</b>
600	300	502	293	1	<b>9673.663</b>
600	400	502	393	1	<b>9673.664</b>
600	600	502	593	1	<b>9673.666</b>
600	800	502	793	1	<b>9673.668</b>
600	1000	502	993	1	<b>9673.660</b>
800	150	702	143	1	<b>9673.681</b>
800	200	702	193	1	<b>9673.682</b>
800	250	702	243	1	<b>9673.687</b>
800	300	702	293	1	<b>9673.683</b>
800	400	702	393	1	<b>9673.684</b>
800	600	702	593	1	<b>9673.686</b>
800	800	702	793	1	<b>9673.688</b>
800	1000	702	993	1	<b>9673.680</b>